

Installation Instructions
Instrucciones de Instalación /
Instructions d'installation /
Installationsanleitung / Istruzioni per l'installazione

TRIPP LITE
SERIES

Fiber Video Extender Kits
Kits extensores de vídeo por fibra
Kits d'extension vidéo par fibre
Fiber Video Extender-Kits
Kit di estensione video in fibra

B127F-1A1-MM-HH
B127F-1A1-MMDDA
B127F-1A1-SM-DD




Purchased product may differ from image.
El producto comprado puede diferir de la imagen.
Le produit acheté peut différer de l'image.
Das gekaufte Produkt kann vom Bild abweichen.
Il prodotto acquistato potrebbe differire dall'immagine.

EATON
Powering Business Worldwide

Installation

Instalación / Installation /
Installation / Installazione


B127F-1A1-MM-HH

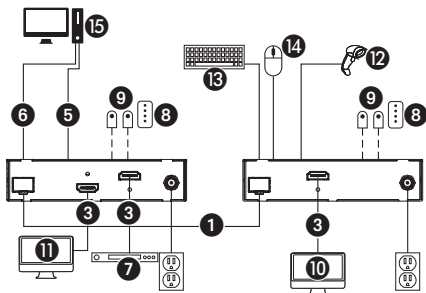

Installation

Instalación / Installation /
Installation / Installazione


B127F-1A1-MMDDA

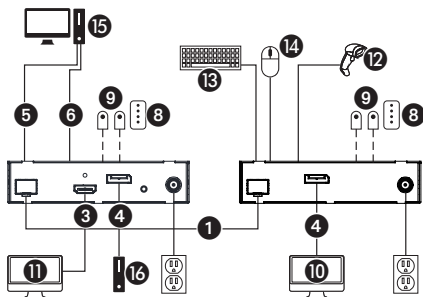

Installation

Instalación / Installation /
Installation / Installazione

B127F-1A1-SM-DD

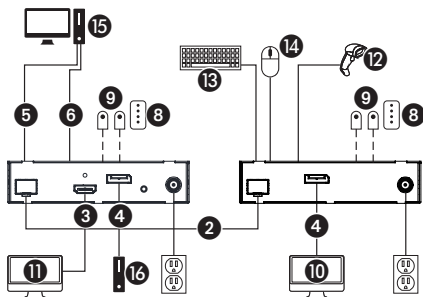

Key

Clave / Légende / Schlüssel / Principale

Cable connections

- 1 Up to 1,000 ft. (305 m) multimode fiber cable
- 2 Up to 32,808 ft. (10 km) singlemode fiber cable
- 3 Up to 15 ft. (4.5 m) HDMI cable at 4K 60 Hz
- 4 Up to 15 ft. (4.5 m) DisplayPort cable at 4K 60 Hz
- 5 Micro-USB cable
- 6 RS-232 cable

Connected components

- 7 HDMI source
- 8 Source remote
- 9 IR sensor
- 10 Display
- 11 Optional local display
- 12 RS-232 scanner (optional)
- 13 USB keyboard
- 14 USB mouse
- 15 Computer with USB (keyboard/mouse) control
- 16 DisplayPort source

Español

Conexiones de cables

- 1 Cable de fibra multimodo hasta 1,000 pies (305 m)
- 2 Cable de fibra monomodo hasta 32,808 pies (10 Km) de
- 3 Cable HDMI a 4 K 60 Hz hasta 15 pies (4.5 m)
- 4 Cable DisplayPort en 4 K 60 Hz hasta 15 pies (4.5 m)
- 5 Cable Micro USB
- 6 Cable RS-232

Componentes conectados

- 7 Fuente HDMI
- 8 Fuente remota
- 9 Sensor IR
- 10 Visualización
- 11 Visualización local opcional
- 12 Escáner RS-232 (opcional)
- 13 Teclado USB
- 14 Ratón USB
- 15 Computadora con control USB (teclado/ratón)
- 16 Fuente DisplayPort

Key

Clave / Légende / Schlüssel / Principale

Français

Connexions de câbles

- 1 Jusqu'à 305 m (1 000 pieds) de câble en fibre multimode
- 2 Jusqu'à 10 km (32 808 pieds) de câble en fibre monomode
- 3 Jusqu'à 4,5 m (15 pieds) de câble HDMI à 4 K 60 Hz
- 4 Jusqu'à 4,5 m (15 pieds) de câble DisplayPort à 4 K 60 Hz
- 5 Micro-câble USB
- 6 Câble RS-232

Composants connectés

- 7 Source HDMI
- 8 Télécommande de la source
- 9 Capteur IR
- 10 Écran
- 11 Écran local en option
- 12 Scanner RS-232 (facultatif)
- 13 Clavier USB
- 14 Souris USB
- 15 Ordinateur avec contrôle USB (clavier/souris)
- 16 Source DisplayPort

6

Deutsch

Kabelverbindungen

- 1 Bis zu 1.000 ft. (305 m) Multimode-Glasfaserkabel
- 2 Bis zu 32,808 ft. (10 km) Singlemode-Glasfaserkabel
- 3 Bis zu 15 ft. (4,5 m) HDMI-Kabel bei 4 K 60 Hz
- 4 Bis zu 15 ft. (4,5 m) DisplayPort-Kabel bei 4 K 60 Hz
- 5 Micro-USB-Kabel
- 6 RS-232 Kabel

Verbundene Komponenten

- 7 HDMI-Quelle
- 8 Ferngesteuerte Quelle
- 9 IR-Sensor
- 10 Display
- 11 Optionales lokales Display
- 12 RS-232 Scanner (optional)
- 13 USB-Tastatur
- 14 USB-Maus
- 15 Computer mit USB-Steuerung (Tastatur/Maus)
- 16 DisplayPort-Quelle

Key

Clave / Légende / Schlüssel / Principale

Italiano

Collegamenti dei cavi

- 1 Cavo in fibra multimodale fino a 1.000 ft. (305 m)
- 2 Cavo in fibra monomodale fino a 32,808 ft. (10 km)
- 3 Cavo HDMI a 4 K 60 Hz fino a 15 ft. (4,5 m) C
- 4 Cavo DisplayPort a 4 K 60 Hz fino a 15 ft. (4,5 m)
- 5 Cavo micro-USB
- 6 Cavo RS-232

Componenti collegati

- 7 Fonte HDMI
- 8 Fonte remota
- 9 Sensore IR
- 10 Display
- 11 Display locale opzionale
- 12 Scanner RS-232 (opzionale)
- 13 Tastiera USB
- 14 Mouse USB
- 15 Computer con controllo USB (tastiera/mouse)
- 16 Fonte DisplayPort



Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

© 2024 Eaton
All Rights Reserved
Publication No.
24-03-128 /
93-49E9_RevA
March 2024

Eaton is a registered
trademark.

All trademarks are
property of their
respective owners.